

A

B

C


D

A

B

C

D

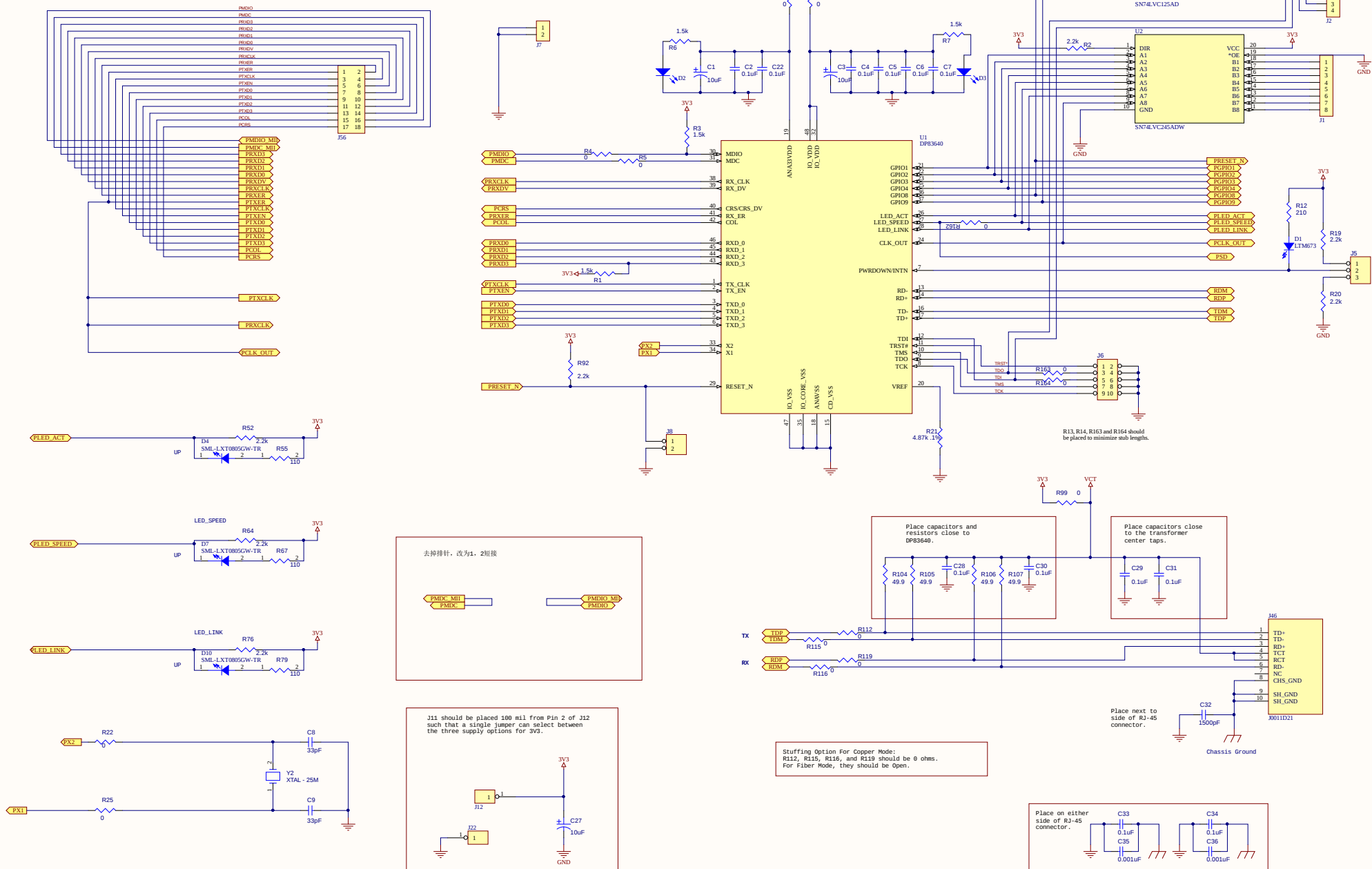

Comment	Description	Designator	Footprint	LibRef	Quantity
10uF		C1, C3, C27	C_7343	CAP_POL_0	3
0.1uF		C2, C4, C5, C6, C7, C22, C28, C29, C30, C31, C33, C34	C0805_L	C-0_0.1uF	12
33pF		C8, C9	C0805_L	SMALL CAP	2
1500pF		C32	C1808_L	SMALL CAP	1
0.001uF		C35, C36	C0805_L	C-0_0.1uF	2
LTM673		D1	LED0805_R	LED LTM673_1	1
LED	发光二极管	D2, D3	LED0805_R	LED	2
SML-LXT0805GW-TR		D4, D7, D10	LED0805_R	LED SML-LXT0805GW- TR	3
HDR-1X8	8P接插件	J1	HDR2.54-LI-8P	Header 8	1
HDR-1X4	4P接插件	J2	HDR2.54-LI-4P	Header 4	1
HDR_1X3		J5	HDR2.54-LI-3P	HDR_1X3_Dup1	1
CON2x5_TH		J6	HDR2.54-LI-2x5P	CON2x5_TH_0	1
HDR-1X2	2P接插件	J7	HDR2.54-LI-2P	Header 2	1
HDR-1X2		J8	HDR1X2	HDR-1X2_Dup1	1
HDR-1X1		J12, J22	HDR2.54-LI-1P	HDR-1X1	2
J0011D21		J46	J0011D21	PulseJack RJ45 J0011D21	1
Header 9X2	9*2P接插件	J56	HDR2.54-LI-2x9P	Header 9X2	1
1.5k		R1	R0603_L	R	1
2.2k		R2, R19, R20, R52, R64, R76, R92	R0805_L	R	7
1.5k		R3, R6, R7	R0805_L	R	3
0		R4, R5, R22, R25, R26, R30, R99, R112, R115, R116, R119, R162, R163, R164	R0805_L	R	14
210		R12	R0805_L	R	1
4.87k .1%		R21	R0805_L	R	1
110		R55, R67, R79	R0805_L	R	3
49.9		R104, R105, R106, R107	R0805_L	R	4
DP83640		U1	DP83640	DP83640T_0	1
SN74LVC245ADW	Octal Bus Transceiver With 3-State Outputs	U2	DW20	SN74LVC245ADW	1
SN74LVC125AD	Quadruple Bus Buffer Gate With 3-State Outputs	U3	D14	SN74LVC125AD	1
XTAL - 25M		Y2	OSC HC-49U	CRYSTAL	1