


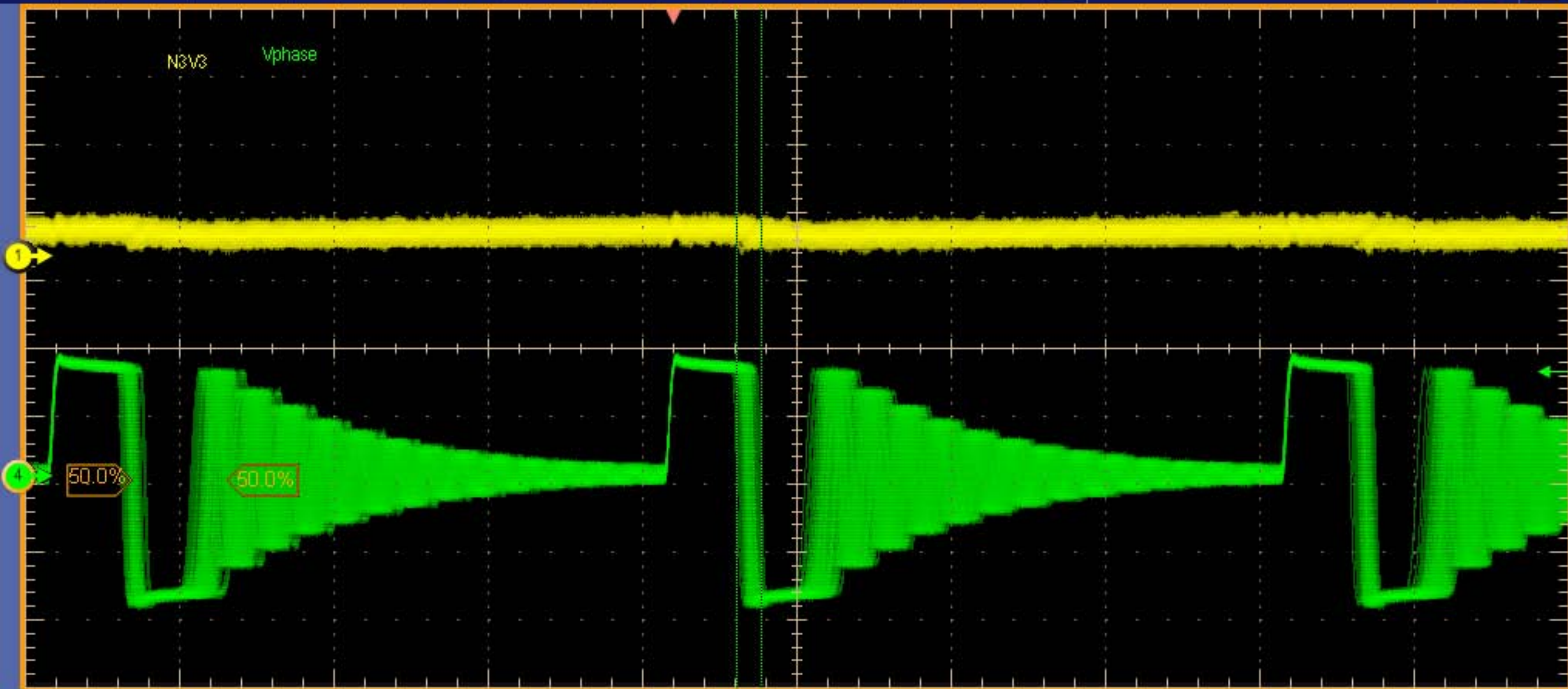

C1 10.0mV Offset:-3.27V 50Ω BW:20.0M
C4 2.0V/div 50Ω BW:20.0M


t1 205.0ns
t2 285.0ns
Δt 80.0ns
1/Δt 12.5MHz

C4 3.08V

500ns 10.0GS/s IT 50.0ps/pt
Stopped
351 acqs RL:100k
November 07, 2012 18:21:10

	Value	Mean	Min	Max	St Dev	Count	Info
C1 Max	-3.262V	-3.2623978	-3.264	-3.261	441.6μ	351.0	
C1 Min	-3.266V	-3.2664234	-3.268	-3.265	509.1μ	351.0	
C1 RMS	3.264V	3.2643815	3.263	3.266	448.8μ	351.0	
C1 Pk-Pk	3.864mV	4.0255292m	3.303m	5.2m	312.2μ	351.0	
C4 Max	3.627V	3.5994441	3.552	3.657	13.7m	351.0	
C4 Min	-3.779V	-3.824031	-3.883	-3.779	26.01m	351.0	
C4 Freq*	3.199MHz	3.204261M	2.88M	3.549M	121.4k	351.0	

0.009A load

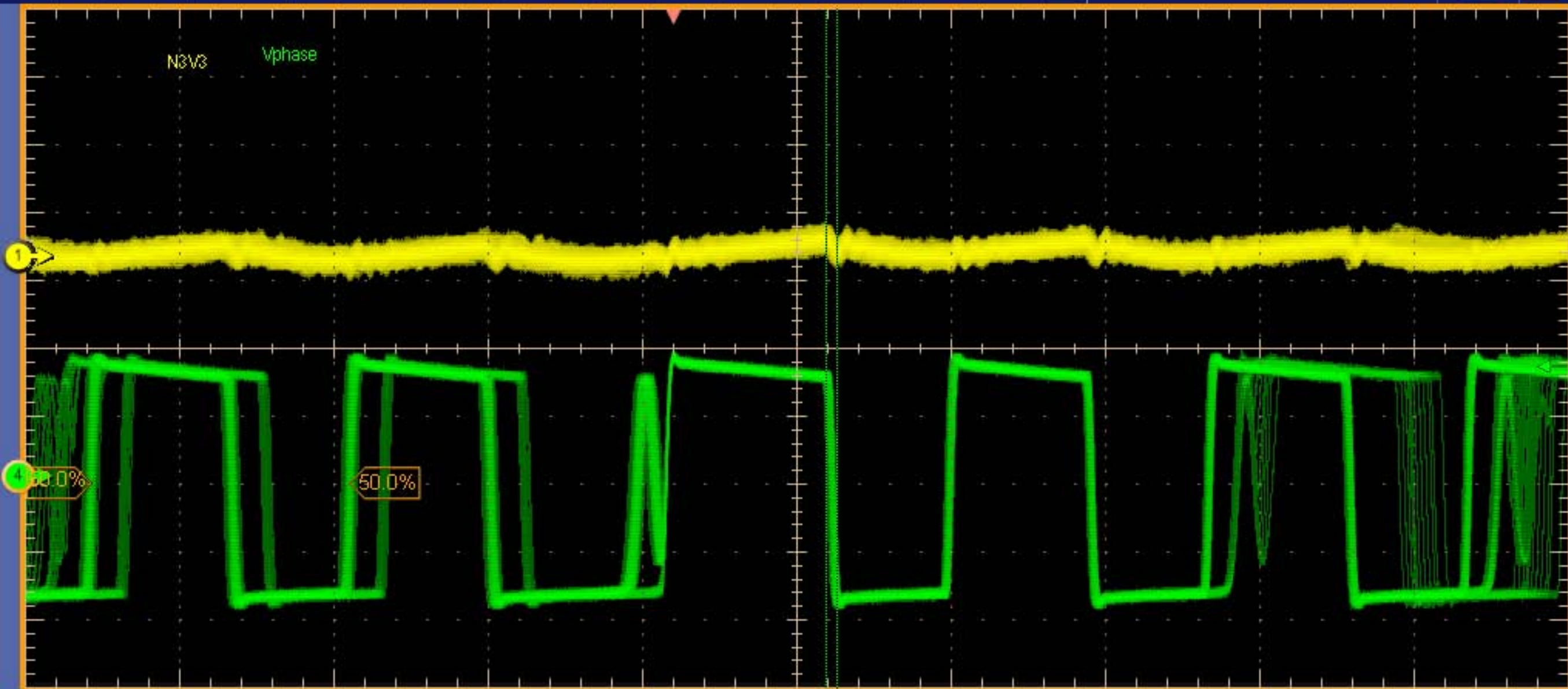

C1 10.0mV Offset:-3.25V 50Ω BW:20.0M
C4 2.0V/div 50Ω BW:20.0M


t1 495.0ns
t2 530.0ns
Δt 35.0ns
1/Δt 28.57MHz

C4 ∫ 3.24V

500ns 10.0GS/s IT 50.0ps/pt
Stopped
327 acqs RL:100k
November 07, 2012 18:19:35

	Value	Mean	Min	Max	St Dev	Count	Info
C1 Max	-3.247V	-3.246515	-3.281	-3.245	633.2μ	740.0	
C1 Min	-3.252V	-3.2520469	-3.284	-3.251	503.2μ	740.0	
C1 RMS	3.25V	3.2494099	3.248	3.283	471.9μ	740.0	
C1 Pk-Pk	5.063mV	5.5319112m	3.023m	8.18m	522.9μ	740.0	
C4 Max	3.68V	3.6290968	3.547	3.706	24.01m	740.0	
C4 Min	-3.84V	-3.8535653	-3.92	-3.716	23.46m	740.0	
C4 Freq*	1.194MHz	1.2720934M	956.3k	6.289G	862.0k	740.0	

0.09A load

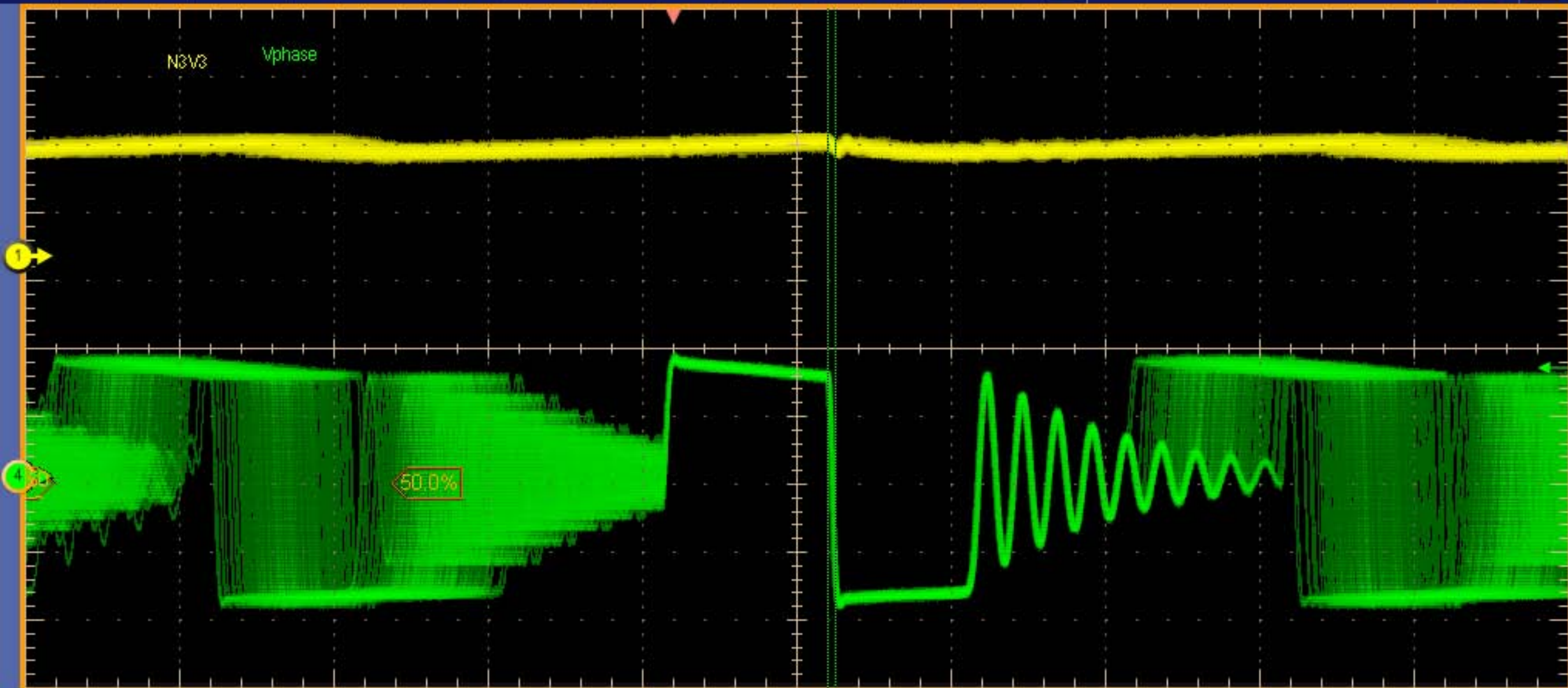

C1 20.0mV Offset:-3.28V 50Ω BW:20.0M

C4 2.0V/div 50Ω BW:20.0M

t1 500.0ns

t2 525.0ns

Δt 25.0ns

1/Δt 40.0MHz

C4 ∫ 3.2V

500ns 10.0GS/s IT 50.0ps/pt

Stopped

375 acqs


RL:100k

November 07, 2012

18:24:17

	Value	Mean	Min	Max	St Dev	Count	Info
C1 Max	-3.249V	-3.24859	-3.25	-3.247	428.8μ	375.0	
C1 Min	-3.256V	-3.2558921	-3.257	-3.255	459.4μ	375.0	
C1 RMS	3.252V	3.2522574	3.251	3.254	396.0μ	375.0	
C1 Pk-Pk	7.516mV	7.3021175m	6.528m	8.541m	334.1μ	375.0	
C4 Max	3.6V	3.5987208	3.544	3.68	14.87m	479.0	
C4 Min	-3.84V	-3.8475583	-3.923	-3.801	15.39m	479.0	
C4 Freq*	912.6kHz	5.9004022M	695.2k	9.241M	3.931M	479.0	

0.045A load

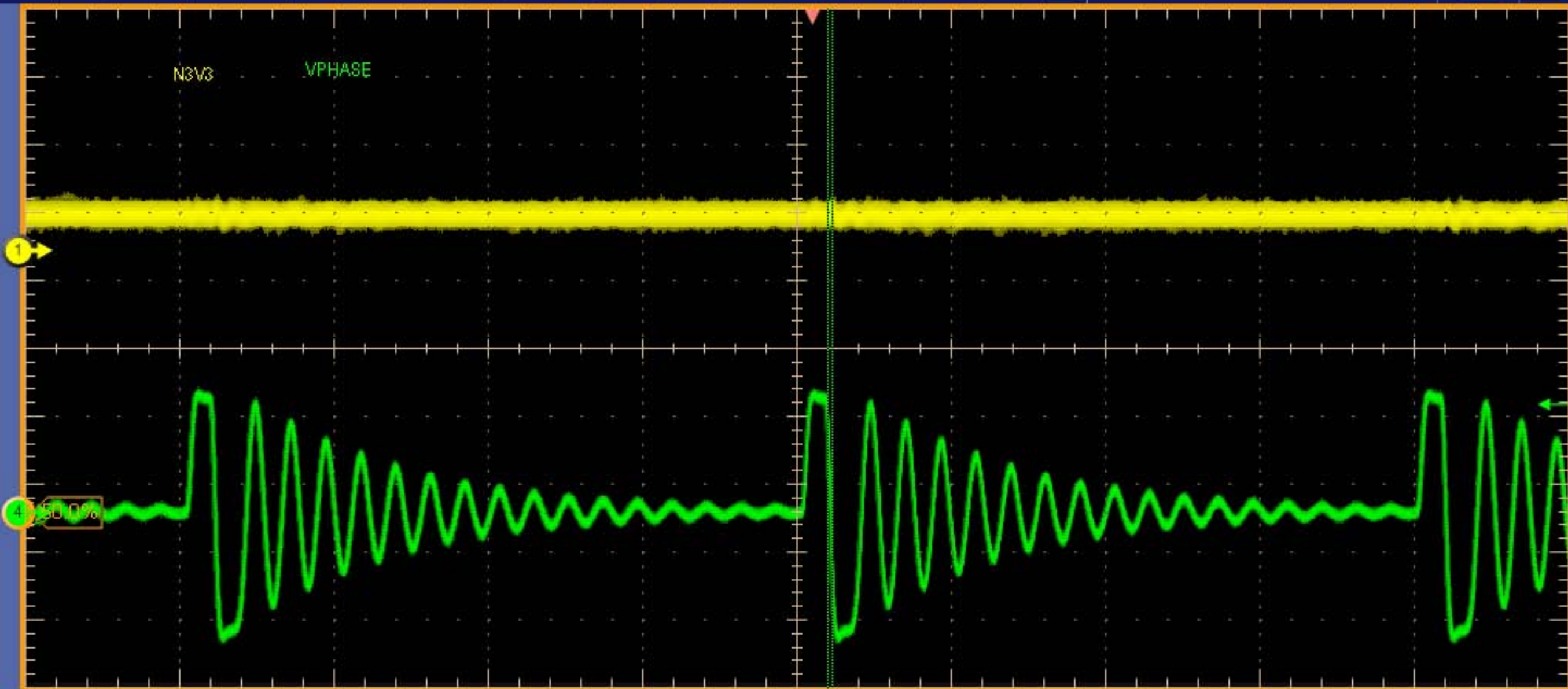

C1 10.0mV Offset:-3.28V 50Ω BW:20.0M
C4 2.0V/div 50Ω BW:20.0M

t1 50.0ns
t2 65.0ns
Δt 15.0ns
1/Δt 66.67MHz

C4 ∫ 3.2V

500ns 10.0GS/s IT 50.0ps/pt
Stopped
766 acqs RL:100k
November 06, 2012 16:15:53

	Value	Mean	Min	Max	St Dev	Count	Info
C1 Max	-3.275V	-3.2746794	-3.276	-3.273	270.0μ	766.0	
C1 Min	-3.279V	-3.278497	-3.28	-3.277	302.7μ	766.0	
C1 RMS	3.277V	3.2766069	3.276	3.277	211.8μ	766.0	
C1 Pk-Pk	4.0mV	3.8176317m	3.031m	5.647m	283.2μ	766.0	
C4 Max	3.611V	3.6214268	3.579	3.72	21.68m	766.0	
C4 Min	-3.736V	-3.7548341	-3.806	-3.72	22.62m	766.0	
C4 Freq*	961.0MHz	1.3569595G	85.02M	5.778G	1.421G	766.0	

no load