


封装注意：
1 仅U1的封装，待定。

PCB板注意：
1 所有GND管脚，与GND覆铜面全连接。

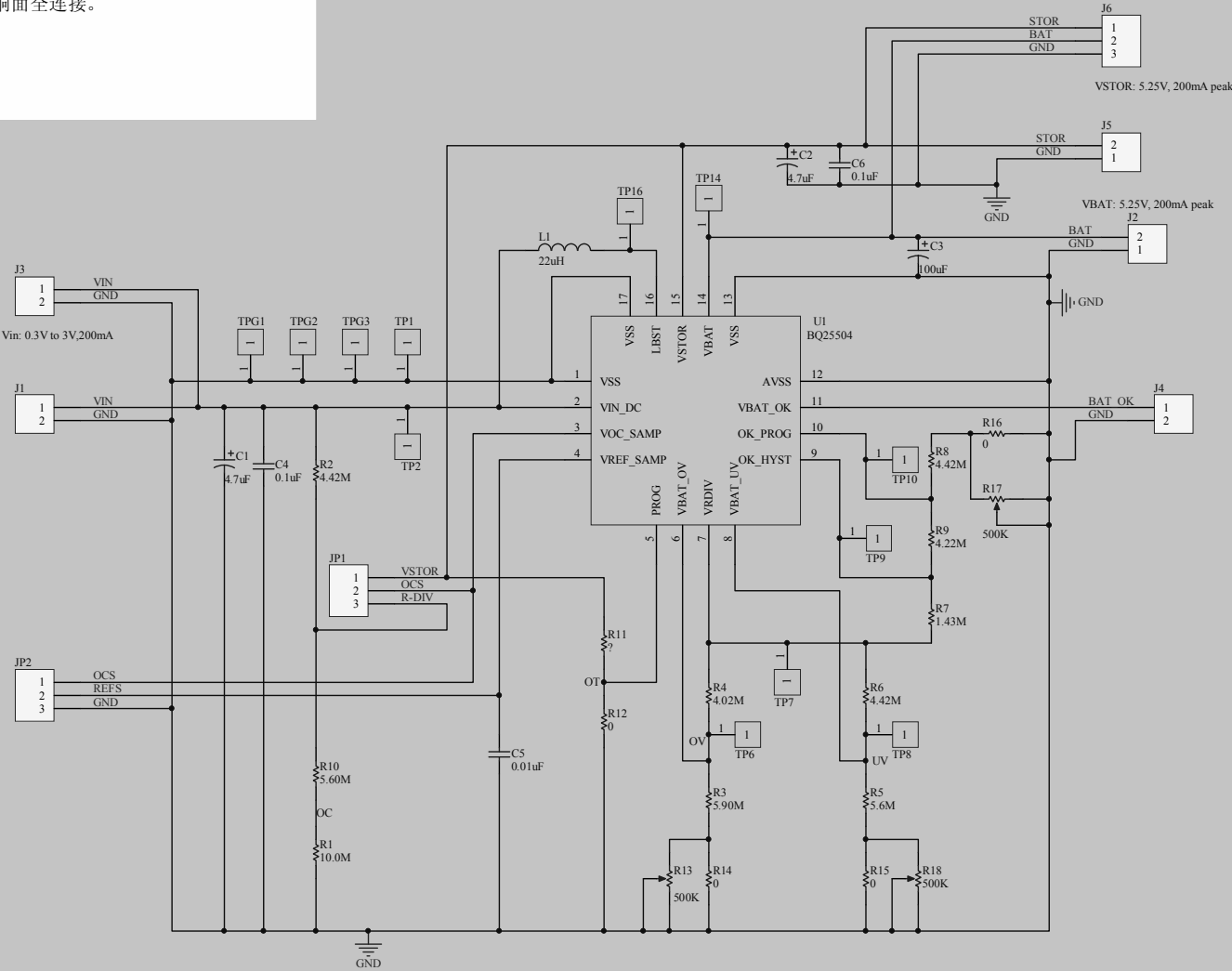

OT: Over temperature setting for 60C(low) or 120C(high);
OV: Over voltage threshold programming resistors;
UV: Under voltage threshold programming resistors;
BAT_OK: STOR Power Good threshold programming resistors;
OC: Open circuit input voltage-resistors program maximum power point tracking(MMPT);
OCS: Open circuit sample;
STOR: Storage voltage - System load connection;

Title		
Size	Number	Revision
A3		
Date:	2014-4-1	Sheet of
File:	E:\开发\BQ25504-Development.SchDoc Drawn By:	